
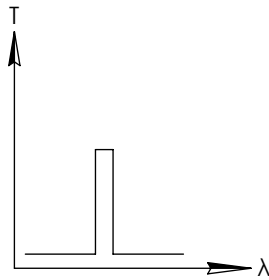
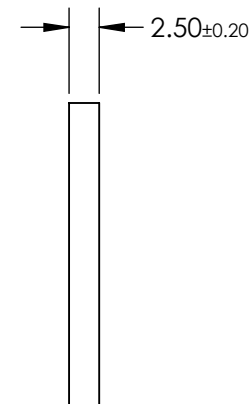
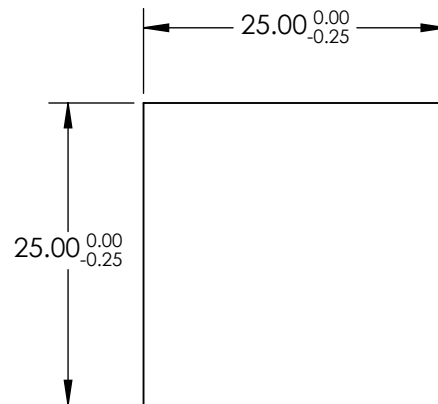


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

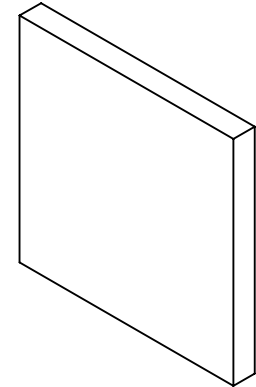

BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	530
FULL WIDTH HALF MAX (FWHM) (nm)	50
SURFACE QUALITY	80-50
CAOTING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED



TITLE	HOYA G530 (VIS) 25mm Square, Colored Glass Bandpass Filter		
DWG NO	34436	SHEET 1 OF 1	

ALL DIMS IN mm