
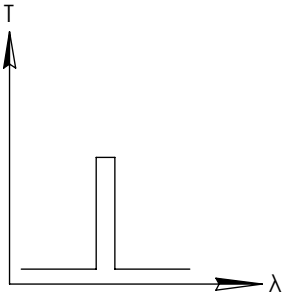
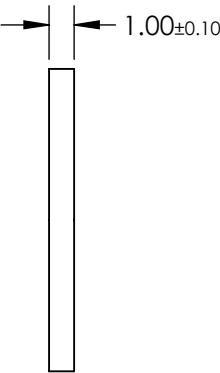
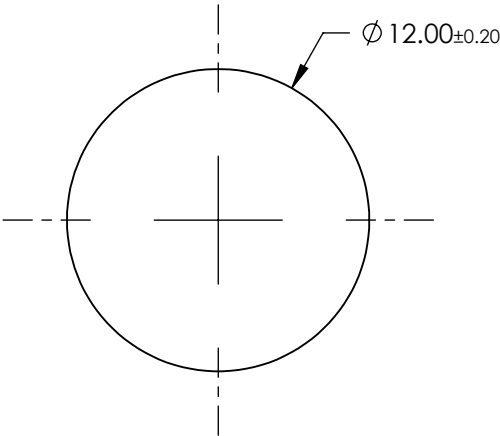


NOTE:

1. SUBSTRATE: COLORED GLASS

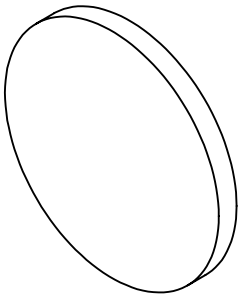

BANDPASS FILTER

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	370.00
FULL WIDTH HALF MAX (FWHM) (nm)	100.00
SURFACE QUALITY	60-40
COATING TYPE	UNCOATED
BEVEL	PROTECTIVE AS NEEDED



THIRD ANGLE  
PROJECTION

ALL DIMS IN

mm

**EO**® Edmund Optics®

TITLE

Hoya B370 (UVVIS) 12mm Dia., 1mm Thick,  
Colored Glass Bandpass Filter

DWG NO

18776

SHEET  
1 OF 1