

[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Industrial and Pointing Lasers](#)

Miniature LDM Focusable Laser Diode Modules




- Line Generation Optics Available
- Bare Leads for Instrument Integration
- Focusable from 35mm to Infinity



Common Specifications

Note:	Includes: Users Manual, Warning Label, and Focus Key	Type of Laser:	Diode
Weight (g):	9.5	Length (mm):	37.00
Beam Divergence (mrad):	<0.5	Focus Range (mm):	35mm - ∞
Output Power Tolerance (%):	±5		
Electrical Leads/ Pin Connections:	red (+), black (-)		
Output Type:	Free Space		

Technical Information

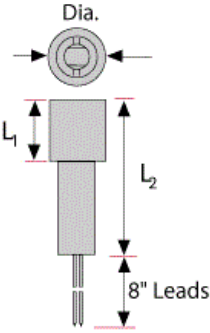

Products

Wavelength (nm)	Output Power (mW)	Beam Size at Nearest Focus (μm)	Beam Diameter (mm)	Beam Divergence (mrad)	Stock Number	Price	Buy
635.00	0.9 (Maximum)	<0.5100	4 x 2	<0.5	#53-232	\$189.00 Volume Pricing	Contact Us
670.00	0.9 (Maximum)	<0.525	4 x 2	<0.5	#39-918	\$189.00 Volume Pricing	5 In Stock
520.00	1 (Maximum)	<25	4 x 2 at Aperture	<0.5	#72-808	\$231.00 Volume Pricing	Contact Us
780.00	1 (Maximum)	<25	4 x 2 at Aperture	<0.5	#72-810	\$189.00 Volume Pricing	1 In Stock
850.00	1 (Maximum)	<25	4 x 2 at Aperture	<0.5	#72-812	\$189.00 Volume Pricing	1 In Stock
520.00	3 (Maximum)	<25	4 x 2 at Aperture	<0.5	#72-809	\$242.00 Volume Pricing	1 In Stock
670.00	3 (Maximum)	<0.525	4 x 2	<0.5	#53-233	\$210.00 Volume Pricing	3 In Stock
780.00	3 (Maximum)	<25	4 x 2 at Aperture	<0.5	#72-811	\$200.00 Volume Pricing	Contact Us
635.00	4.5 (Maximum)	<0.525	4 x 2	<0.5	#53-755	\$226.00 Volume Pricing	2 In Stock
850.00	3 (Maximum)	<25	4 x 2 at Aperture	<0.5	#72-813	\$200.00 Volume Pricing	1 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com